

## SET: MULTI V-BLOCK

HWS 190/SET

### PRODUCT DESCRIPTION


- » Consisting of HWS 190, HWS 1902 and HWS 1905
- » Enables the clamping of blade ejectors
- » Enables efficient clamping for the grinding of standard ejectors, ejector sleeves and round and square cutting punches
- » Measurement possible in tensioned state

### MATERIAL

- » 1.2379

### RECOMMENDATION FOR USE

- » Clamping range A: for  $\varnothing$  0.5 mm to  $\varnothing$  6 mm
- » Clamping range B: for  $\varnothing$  3 mm to  $\varnothing$  20 mm

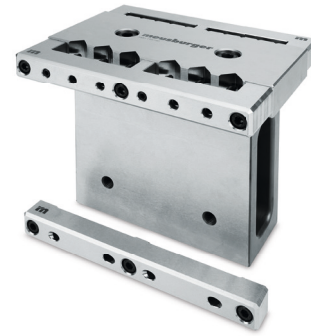

b	h	l	No.	EUR
148	155	180	HWS 190/Set	<>

## MULTI V-BLOCK

HWS 190

### PRODUCT DESCRIPTION


- » Enables efficient clamping for subsequent grinding of standard ejectors, ejector sleeves and round as well as square cutting punches
- » Measurement possible in tensioned state

### MATERIAL

- » 1.2379

### RECOMMENDATION FOR USE

- » Clamping range A: for  $\varnothing$  0.5 mm to  $\varnothing$  6 mm
- » Clamping range B: for  $\varnothing$  3 mm to  $\varnothing$  20 mm

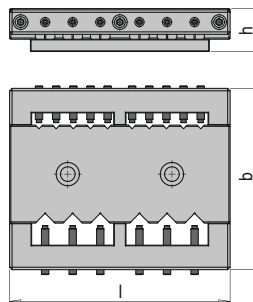

b	h	l	No.	EUR
148	35	180	HWS 190/180	<>