




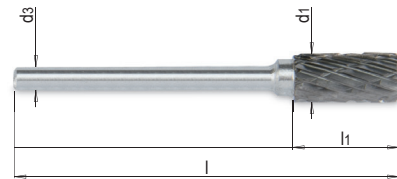


 



PRODUCT DESCRIPTION

- » Shank Ø3 mm
- » For pre-toughened and hardened steel < 54 HRC, chrome steel and plastics



	Shape		d3	l	d1	l1	No.	EUR
A2		Cylinder, cross lines	3	51	6	12	V 72243/ A2/ 6,0x12,0	< >
A3		Cylinder, ball nose	3	51	6	12	V 72243/ A3/ 6,0x12,0	< >
E2		Inverted cone, cross lines	3	51	6	6	V 72243/ E2/ 6,0x 6,0	< >
G3		Cone, pointed tip	3	51	6	12	V 72243/ G3/ 6,0x12,0	< >
J1		Ball	3	51	6	-	V 72243/ J1/ 6,0	< >
L1		Tree, pointed tip	3	51	6	12	V 72243/ L1/ 6,0x12,0	< >
L2		Tree, rounded tip	3	51	6	12	V 72243/ L2/ 6,0x12,0	< >
M3		Flame	3	40	5.3	13.5	V 72243/ M3/ 5,3x13,5	< >
M4		Drop	3	48	6	9.5	V 72243/ M4/ 6,0x 9,5	< >

 Cutting data on page PL