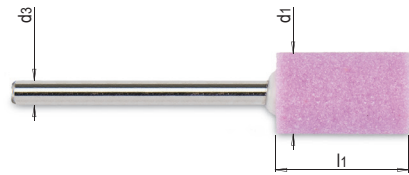


 
 
 



PRODUCT DESCRIPTION

- » Shank Ø3 mm
- » Holds its shape due to hard bond
- » Pink aluminium oxide
- » For pre-toughened and hardened steel < 64 HRC and chrome steel



	Shape	d3	d1	l1	Grit	 Pcs. / PU	No.	EUR
A1	 Cylinder	3	3	8	120	10	V 72423/ A1/ 3x 8/120	<>
		3	4	10	120	10	V 72423/ A1/ 4x10/120	<>
		3	5	10	120	10	V 72423/ A1/ 5x10/120	<>
		3	6	12	120	10	V 72423/ A1/ 6x12/120	<>
		3	8	16	120	10	V 72423/ A1/ 8x16/120	<>
		3	10	16	120	10	V 72423/ A1/10x16/120	<>
C1	 Wheel	3	13	2	120	10	V 72423/ C1/13x 2/120	<>
		3	13	3	120	10	V 72423/ C1/13x 3/120	<>
		3	16	2	120	10	V 72423/ C1/16x 2/120	<>
		3	16	3	120	10	V 72423/ C1/16x 3/120	<>
G1	 Cone	3	8	16	120	10	V 72423/ G1/ 8x16/120	<>
		3	12	24	120	10	V 72423/ G1/12x24/120	<>
G2	 Truncated cone	3	4	12	120	10	V 72423/ G2/ 4x12/120	<>
		3	7	10	120	10	V 72423/ G2/ 7x10/120	<>
J1	 Ball	3	3.5	-	120	10	V 72423/ J1/ 3,5/120	<>
		3	4	-	120	10	V 72423/ J1/ 4 /120	<>
		3	6	-	120	10	V 72423/ J1/ 6 /120	<>
		3	8	-	120	10	V 72423/ J1/ 8 /120	<>
		3	10	-	120	10	V 72423/ J1/10 /120	<>
		3	12	-	120	10	V 72423/ J1/12 /120	<>