


PRODUKTBESCHREIBUNG

» Nach VDI 3366

MATERIAL

» 1.1191 \approx 700 N/mm²

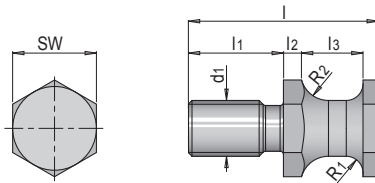

max. kg	SW	l	l1	l2	l3	R1	R2	d1	Nr.	EUR
320	24	58	28	5,5	20	6	10	M16	E 1280/16	<>
500	30	68	34	6,5	22	6	10	M20	E 1280/20	<>
1.000	36	78	38	8	25	6	10	M24	E 1280/24	<>
1.500	41	95	45	10	32	6	10	M30	E 1280/30	<>
2.500	50	118	56	12	40	8	12	M36	E 1280/36	<>

i Aus Sicherheitsgründen stets berücksichtigen, dass zwei Tragzapfen das gesamte Werkzeuggewicht tragen müssen.

