






 


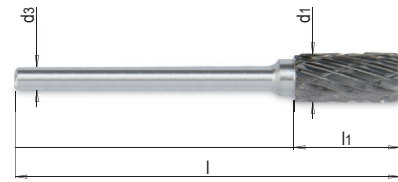

PRODUKTBESCHREIBUNG

- » Schaft Ø3 mm
- » Für vergüteten und gehärteten Stahl < 54 HRC, Chromstahl und Kunststoffe geeignet



	Form		d3	l	d1	l1	Nr.	EUR
A2		Zyl. stirnverzahnt	3	51	6	12	V 72243/ A2/ 6,0x12,0	< >
A3		Zylinder rund	3	51	6	12	V 72243/ A3/ 6,0x12,0	< >
E2		Trapez stirnverzahnt	3	51	6	6	V 72243/ E2/ 6,0x 6,0	< >
G3		Spitzkegel	3	51	6	12	V 72243/ G3/ 6,0x12,0	< >
J1		Kugel	3	51	6	-	V 72243/ J1/ 6,0	< >
L1		Spitzbogen	3	51	6	12	V 72243/ L1/ 6,0x12,0	< >
L2		Rundbogen	3	51	6	12	V 72243/ L2/ 6,0x12,0	< >
M3		Flamme	3	40	5,3	13,5	V 72243/ M3/ 5,3x13,5	< >
M4		Tropfen	3	48	6	9,5	V 72243/ M4/ 6,0x 9,5	< >

 Schnittwerte auf Seite PL