


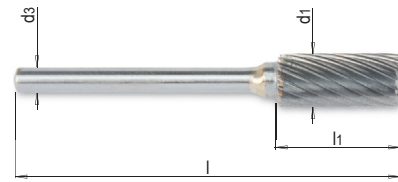







PRODUKTBESCHREIBUNG

- » Schaft Ø3 mm
- » Für vergüteten und gehärteten Stahl < 54 HRC sowie Chromstahl geeignet



	Form		d3	l	d1	l1	Nr.	EUR
A1		Zylinder	3	43	6	13	V 72246/ A1/ 6,0x13,0	< >
A2		Zyl. stirnverzahnt	3	43	6	13	V 72246/ A2/ 6,0x13,0	< >
A3		Zylinder rund	3	43	6	14	V 72246/ A3/ 6,0x14,0	< >
E2		Trapez stirnverzahnt	3	36	6	6	V 72246/ E2/ 6,0x 6,0	< >
G3		Spitzkegel	3	43	6	13	V 72246/ G3/ 6,0x13,0	< >
J1		Kugel	3	35	6	-	V 72246/ J1/ 6,0	< >
L2		Rundbogen	3	43	6	13	V 72246/ L2/ 6,0x13,0	< >
M4		Tropfen	3	40	6	10	V 72246/M4/ 6,0x10,0	< >

 Schnittwerte auf Seite PL