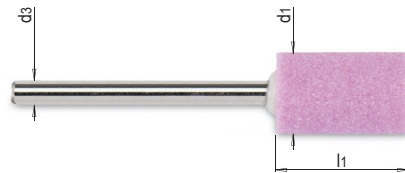


 
 
 



### PRODUKTBESCHREIBUNG

- » Schaft Ø3 mm
- » Durch harte Bindung sehr formstabil
- » Edelmetallkorund rosa
- » Für vergüteten und gehärteten Stahl < 64 HRC und Chromstahl geeignet



Form		d3	d1	l1	Korn	 Stk. / VPE	Nr.	EUR	
A1		Zylinder	3	3	8	120	10	V 72423/ A1/ 3x 8/120	<>
			3	4	10	120	10	V 72423/ A1/ 4x10/120	<>
			3	5	10	120	10	V 72423/ A1/ 5x10/120	<>
			3	6	12	120	10	V 72423/ A1/ 6x12/120	<>
			3	8	16	120	10	V 72423/ A1/ 8x16/120	<>
			3	10	16	120	10	V 72423/ A1/10x16/120	<>
C1		Rad	3	13	2	120	10	V 72423/ C1/13x 2/120	<>
			3	13	3	120	10	V 72423/ C1/13x 3/120	<>
			3	16	2	120	10	V 72423/ C1/16x 2/120	<>
			3	16	3	120	10	V 72423/ C1/16x 3/120	<>
G1		Kegel	3	8	16	120	10	V 72423/ G1/ 8x16/120	<>
			3	12	24	120	10	V 72423/ G1/12x24/120	<>
G2		Kegel flach	3	4	12	120	10	V 72423/ G2/ 4x12/120	<>
			3	7	10	120	10	V 72423/ G2/ 7x10/120	<>
J1		Kugel	3	3,5	-	120	10	V 72423/ J1/ 3,5/120	<>
			3	4	-	120	10	V 72423/ J1/ 4 /120	<>
			3	6	-	120	10	V 72423/ J1/ 6 /120	<>
			3	8	-	120	10	V 72423/ J1/ 8 /120	<>
			3	10	-	120	10	V 72423/ J1/10 /120	<>
			3	12	-	120	10	V 72423/ J1/12 /120	<>