



### PRODUKTBESCHREIBUNG

» Für Wendepplatten

E 1 - E 17

E 18 - E 24

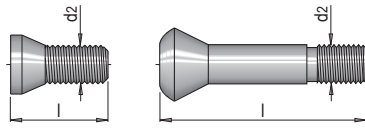

E <sup>1)</sup>	Nm	d2	l	Ausführung	 Stk. / VPE	Nr.	EUR
E 1	0,7	M2	3,3	T 6	10	WZE 100/2 x 3,3/T 6	<>
E 2	1,2	M2.5	5	T 8	10	WZE 100/2,5x 5 /T 8	<>
E 3	3,2	M3.5	7,2	T15	10	WZE 100/3,5x 7,2/T15	<>
E 4	3,2	M3.5	8,6	T15	10	WZE 100/3,5x 8,6/T15	<>
E 5	4	M4.5	10,5	T20	10	WZE 100/4,5x10,5/T20	<>
E 6	2	M3	7,3	T10	10	WZE 100/3 x 7,3/T10	<>
E 7	1	M2.2	4,2	7IP	10	WZE 100/2,2x 4,2/ 7IP	<>
E 8	1,6	M2.5	5	8IP	10	WZE 100/2,5x 5 / 8IP	<>
E 9	1,6	M2.5	5,6	8IP	10	WZE 100/2,5x 5,6/ 8IP	<>
E10	3,2	M3.5	8,6	15IP	10	WZE 100/3,5x 8,6/15IP	<>
E11	1,6	M2.5	7,3	8IP	10	WZE 100/2,5x 7,3/ 8IP	<>
E12	0,7	M2	4,3	6IP	10	WZE 100/2 x 4,3/ 6IP	<>
E13	1	M2.2	5	7IP	10	WZE 100/2,2x 5 / 7IP	<>
E14	1,2	M2.5	6	8IP	10	WZE 100/2,5x 6 / 8IP	<>
E15	2,2	M3	7	9IP	10	WZE 100/3 x 7 / 9IP	<>
E16	3,2	M3.5	8,7	15IP	10	WZE 100/3,5x 8,7/15IP	<>
E17	5	M4.5	10,5	20IP	10	WZE 100/4,5x10,5/20IP	<>
E18	0,5	M2.5	5	T 6	10	WZE 100/2,5x 5 /T 6	<>
E19	1	M3	6,9	T 8	10	WZE 100/3 x 6,9/T 8	<>
E20	3	M4	8,5	T15	10	WZE 100/4 x 8,5/T15	<>
E21	4	M5	9,1	T20	10	WZE 100/5 x 9,1/T20	<>
E22	5	M5	12,7	T20	10	WZE 100/5 x12,7/T20	<>
E23	5	M5	15,3	T20	10	WZE 100/5 x15,3/T20	<>
E24	8	M6	20,5	T30	10	WZE 100/6 x20,5/T30	<>

1) Ersatzteil-ID