


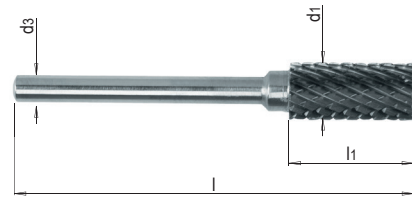








PRODUKTBESCHREIBUNG

- » Schaft Ø3 mm
- » Auch für gehärtete Werkstoffe
- » Für vergüteten und gehärteten Stahl bis 55 HRC
- » Hohe Oberflächengüte



	Form	d3	l	d1	l1	Nr.	EUR
A1		3	43	6	13	V 72245/ A1/6,0x13,0	<>
A2		3	43	6	13	V 72245/ A2/6,0x13,0	<>
A3		3	43	6	14	V 72245/ A3/6,0x14,0	<>
G1		3	48	6	18	V 72245/ G1/6,0x18,0	<>
G3		3	43	6	13	V 72245/ G3/6,0x13,0	<>
J1		3	35	6	-	V 72245/ J1/6,0	<>
L1		3	43	6	13	V 72245/ L1/6,0x13,0	<>
L2		3	43	6	13	V 72245/ L2/6,0x13,0	<>
M4		3	40	6	10	V 72245/ M4/6,0x10,0	<>

 Schnittwerte auf Seite IL