





### PRODUKTBESCHREIBUNG

- » Schaft ø 6 mm
- » Zum Entgraten oder Ansenken einer Bohrung

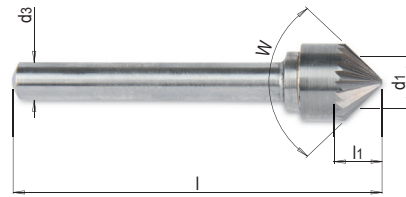

Form	l	l1	d3	W	d1	Nr.	EUR
	50	6	6	60°	6	V 72276/60/ 6	<>
	53	8	6	60°	8	V 72276/60/ 8	<>
	55	10	6	60°	10	V 72276/60/10	<>
	57	12	6	60°	12	V 72276/60/12	<>
	50	4	6	90°	4	V 72276/90/ 4	<>
	50	6	6	90°	6	V 72276/90/ 6	<>
	53	8	6	90°	8	V 72276/90/ 8	<>
	55	10	6	90°	10	V 72276/90/10	<>
	57	12	6	90°	12	V 72276/90/12	<>

 Schnittwerte auf Seite IL