


### PRODUKTBESCHREIBUNG

» Nach DIN 6314

### MATERIAL

» Vergütungsstahl, lackiert

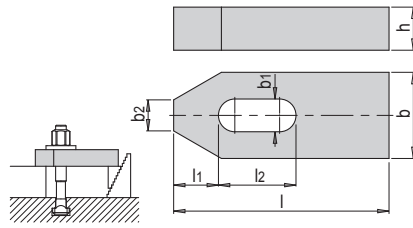

b	b2	h	l1	l2	M <sup>1)</sup>	b1	l	Nr.	EUR
20	8	10	10	20	M6	6,6	50	HWS 112/ 6,6/ 50	<>
25	10	12	13	22	M8	9	60	HWS 112/ 9 / 60	<>
30	12	15	15	30	M10	11	80	HWS 112/11 / 80	<>
40	14	20	21	40	M12, M14	14	100	HWS 112/14 /100	<>
40	14	20	21	50	M12, M14	14	125	HWS 112/14 /125	<>
50	18	25	26	45	M16, M18	18	125	HWS 112/18 /125	<>
50	18	25	26	65	M16, M18	18	160	HWS 112/18 /160	<>
60	22	30	30	60	M20, M22	22	160	HWS 112/22 /160	<>
60	22	30	30	80	M20, M22	22	200	HWS 112/22 /200	<>

1) M: Passend für Spanschraube