


PRODUKTBESCHREIBUNG


- » Mit gehärteten Lagerbuchsen
- » Haken vergütet
- » Ergonomischer Handgriff aus zwei Komponenten

MATERIAL

- » Stahl, verzinkt und passiviert

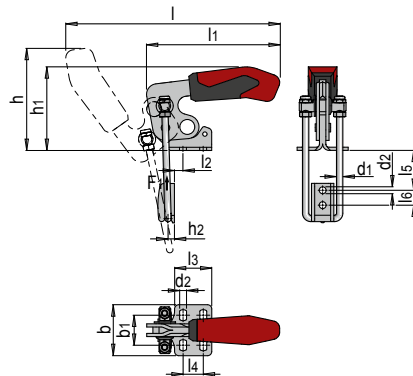

b	h	l	b1	d1	h1	l1	d2	h2	l2	l3	l4	l5 min.	l5 max.	l6	Typ	Nr.	EUR
38	99	158	19,5 - 23,5	4	47	91	5,2	4,5	6,4	26	13	5	30	11	2	HWS 252/ 2	<>
48	136	190	24,5 - 32	6	70	125	6,5	6	8	35	19	7	36	14	3	HWS 252/ 3	<>

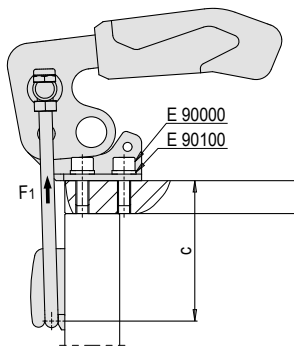

Typ	F1	c min.	c max.
2	1,6 kN	24	49
3	3,2 kN	34,5	64