





 


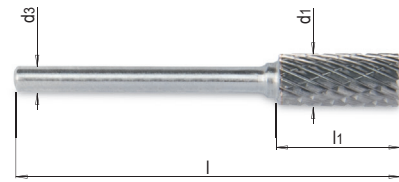

VHM ROTORFRÄSER MIT KREUZVERZÄHNUNG, SCHAFT Ø 3, PREMMW244

PRODUKTBESCHREIBUNG

- » Schaft Ø3 mm
- » Lange Standzeit
- » Hohe Schneidkantenstabilität
- » Für vergüteten und gehärteten Stahl < 54 HRC und Chromstahl geeignet



	Form	d3	l	d1	l1	Nr.	EUR
A1		3	43	6	13	V 72244/ A1/ 6,0x13,0	< >
A2		3	43	6	13	V 72244/ A2/ 6,0x13,0	< >
A3		3	43	6	14	V 72244/ A3/ 6,0x14,0	< >
E1		3	36	6	6	V 72244/ E1/ 6,0x 6,0	< >
G3		3	43	6	13	V 72244/G3/ 6,0x13,0	< >
J1		3	35	6	-	V 72244/ J1/ 6,0	< >
L2		3	43	6	13	V 72244/ L2/ 6,0x13,0	< >
M4		3	40	6	10	V 72244/M4/ 6,0x10,0	< >

 Schnittwerte auf Seite PL