




**PRODUCT DESCRIPTION**

- » Shank Ø3 mm
- » For deburring or countersinking

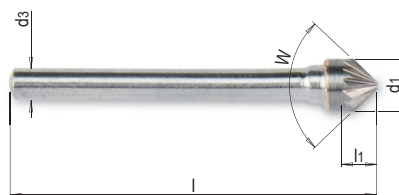

Shape	l	l1	d3	W	d1	No.	EUR
	38	3	3	60°	3	V 72274/60/ 3	<>
	37	7	3	60°	6	V 72274/60/ 6	<>
	38	2	3	90°	3	V 72274/90/ 3	<>
	34	4	3	90°	5	V 72274/90/ 5	<>

 Cutting data on page PL