




### PRODUCT DESCRIPTION

- » Dial indicator in smallest design, ideal for jigs
- » Adjustable tolerance markers
- » Stainless clamping shank
- » Ideal for MAU 5004

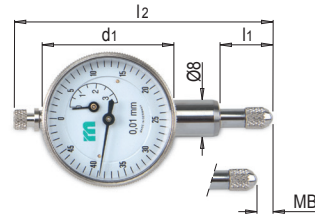

l1	l2	d1	Weight	Fn	SK <sup>1)</sup>	t max.	MB/U <sup>2)</sup>	MB <sup>3)</sup>	No.	EUR
11.4	55	28	37	0.8 N	0,01	40	0,5	3,5	MUA 10240/3,5	<>

1) SK: dial

2) MB/U: measuring range per revolution

3) MB: measuring range