

SET: GENERAL PURPOSE POLISHING STONES, ALUMINIUM OXIDE, MEDIUM BOND V 76130/SET

 
PRODUCT DESCRIPTION

- » Oil soaked general purpose stone with high cutting performance, for tool steel
- » Dimensionally stable bond

APPLICATION

- » Use polishing oil
- » For polishing by hand or with hand filing machines



Set contents	l	s	b	Grit	 Pcs. / PU	No.	EUR
» V 76130 Polishing stone test set	150	3	13	150, 220, 320, 400, 600	1	V 76130/Set-R	<>
	150	6	13	220, 320, 400, 600	1	V 76130/6x13/Set-R	<>


GENERAL PURPOSE POLISHING STONE, ALUMINIUM OXIDE, MEDIUM BOND V 76130

 
PRODUCT DESCRIPTION

- » Oil soaked general purpose stone with high cutting performance, for tool steel
- » Dimensionally stable bond

APPLICATION

- » Use polishing oil
- » For polishing by hand or with hand filing machines

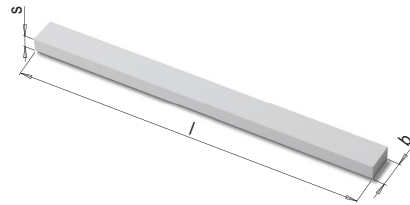

l	s	b	Grit	 Pcs. / PU	No.	EUR
150	3	6	220	12	V 76130/ 3x 6/220	<>
150	3	6	320	12	V 76130/ 3x 6/320	<>
150	3	6	400	12	V 76130/ 3x 6/400	<>
150	3	6	600	12	V 76130/ 3x 6/600	<>
150	3	13	220	12	V 76130/ 3x13/220	<>
150	3	13	320	12	V 76130/ 3x13/320	<>
150	3	13	400	12	V 76130/ 3x13/400	<>
150	3	13	600	12	V 76130/ 3x13/600	<>
150	6	6	150	12	V 76130/ 6x 6/150	<>
150	6	6	220	12	V 76130/ 6x 6/220	<>
150	6	6	320	12	V 76130/ 6x 6/320	<>
150	6	6	400	12	V 76130/ 6x 6/400	<>
150	6	6	600	12	V 76130/ 6x 6/600	<>
150	6	13	150	12	V 76130/ 6x13/150	<>
150	6	13	220	12	V 76130/ 6x13/220	<>
150	6	13	320	12	V 76130/ 6x13/320	<>
150	6	13	400	12	V 76130/ 6x13/400	<>
150	6	13	600	12	V 76130/ 6x13/600	<>
150	10	10	150	12	V 76130/10x10/150	<>
150	10	10	220	12	V 76130/10x10/220	<>
150	10	10	320	12	V 76130/10x10/320	<>
150	10	10	400	12	V 76130/10x10/400	<>
150	10	10	600	12	V 76130/10x10/600	<>