

PRODUCT DESCRIPTION

» Refillable with V 56002 individual containers

INCLUDED IN THE DELIVERY


- » 15 precision gauge tapes
- » Lacquered steel wall holder with large lettering
- » Fixing material for wall holder



Content	No.	EUR
15 precision gauge tapes 0.01 - 0.25	V 56002/Set 0,01-0,25	<>
15 precision gauge tapes 0.30 - 1.00	V 56002/Set 0,30-1,00	<>

PRECISION GAUGE TAPE

V 56002

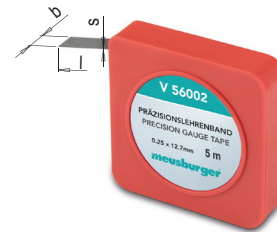

Material	s Tolerance +/-	s	b	l	No.	EUR
1.4310	0.002	0.01	12.7	5 m	V 56002/0,01/12,7/ 5	<>
1.4310	0.002	0.02	12.7	5 m	V 56002/0,02/12,7/ 5	<>
1.1274	0.003	0.03	12.7	5 m	V 56002/0,03/12,7/ 5	<>
1.1274	0.003	0.04	12.7	5 m	V 56002/0,04/12,7/ 5	<>
1.1274	0.003	0.05	12.7	5 m	V 56002/0,05/12,7/ 5	<>
1.1274	0.003	0.06	12.7	5 m	V 56002/0,06/12,7/ 5	<>
1.1274	0.004	0.07	12.7	5 m	V 56002/0,07/12,7/ 5	<>
1.1274	0.004	0.08	12.7	5 m	V 56002/0,08/12,7/ 5	<>
1.1274	0.004	0.09	12.7	5 m	V 56002/0,09/12,7/ 5	<>
1.1274	0.004	0.10	12.7	5 m	V 56002/0,10/12,7/ 5	<>
1.1274	0.004	0.12	12.7	5 m	V 56002/0,12/12,7/ 5	<>
1.1274	0.005	0.15	12.7	5 m	V 56002/0,15/12,7/ 5	<>
1.1274	0.005	0.18	12.7	5 m	V 56002/0,18/12,7/ 5	<>
1.1274	0.006	0.20	12.7	5 m	V 56002/0,20/12,7/ 5	<>
1.1274	0.007	0.25	12.7	5 m	V 56002/0,25/12,7/ 5	<>
1.1274	0.007	0.30	12.7	5 m	V 56002/0,30/12,7/ 5	<>
1.1274	0.008	0.35	12.7	5 m	V 56002/0,35/12,7/ 5	<>
1.1274	0.009	0.40	12.7	5 m	V 56002/0,40/12,7/ 5	<>
1.1274	0.009	0.45	12.7	5 m	V 56002/0,45/12,7/ 5	<>
1.1274	0.01	0.50	12.7	5 m	V 56002/0,50/12,7/ 5	<>
1.1274	0.01	0.55	12.7	5 m	V 56002/0,55/12,7/ 5	<>
1.1274	0.01	0.60	12.7	5 m	V 56002/0,60/12,7/ 5	<>
1.1274	0.012	0.65	12.7	5 m	V 56002/0,65/12,7/ 5	<>
1.1274	0.012	0.70	12.7	5 m	V 56002/0,70/12,7/ 5	<>
1.1274	0.012	0.75	12.7	5 m	V 56002/0,75/12,7/ 5	<>

Material	s Tolerance +/-	s	b	l	No.	EUR
1.1274	0.013	0.80	12.7	5 m	V 56002/0,80/12,7/ 5	<>
1.1274	0.013	0.85	12.7	5 m	V 56002/0,85/12,7/ 5	<>
1.1274	0.013	0.90	12.7	5 m	V 56002/0,90/12,7/ 5	<>
1.1274	0.013	0.95	12.7	5 m	V 56002/0,95/12,7/ 5	<>
1.1274	0.018	1.00	12.7	5 m	V 56002/1,00/12,7/ 5	<>