





PRODUCT DESCRIPTION

- » Shackle can be swivelled and fixed in a wide range
- » 360° rotatable - positioning in load direction
- » Loadable in any direction
- » 100% crack tested screw

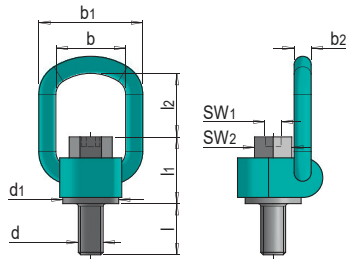

SW1	SW2	b	b1	b2	l	l1	l2	d1	d	max. kg	max. kg	max. kg	max. kg	No.	EUR
10	24	45	67	11	20	43	41	36	M 8	300	300	600	400	E 1275 M/ 8	<>
10	24	45	67	11	20	43	41	36	M10	630	630	1,260	850	E 1275 M/10	<>
10	24	45	67	11	20	43	41	36	M12	1,000	1,000	2,000	1,400	E 1275 M/12	<>
10	24	45	67	11	24	43	41	36	M16	1,500	1,500	3,000	2,100	E 1275 M/16	<>
8	24	54	81	13	33	44	55	50	M20	2,500	2,500	5,000	3,500	E 1275 M/20	<>
14	36	54	87	17	36	58	67	45	M24	4,000	4,000	8,000	5,600	E 1275 M/24	<>
14	36	75	115	20	45	55	68	67	M30	6,000	6,000	12,000	8,500	E 1275 M/30	<>

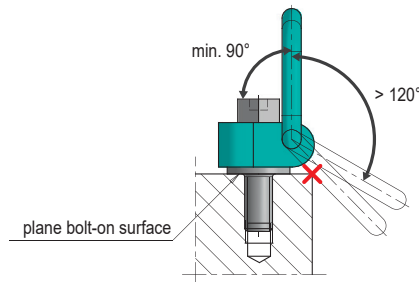

Do not rotate under load!

Rotate in the direction of force before loading!