


PRODUCT DESCRIPTION


- » With hardened bushings
- » Tempered hook
- » Ergonomic handle made of two components

MATERIAL

- » Steel, galvanised and passivated

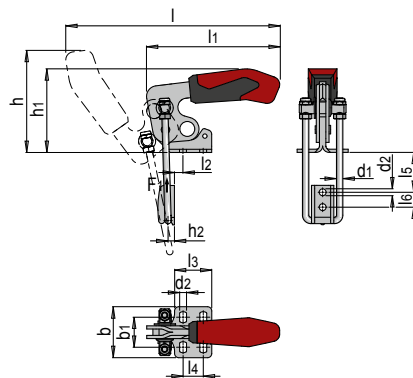

b	h	l	b1	d1	h1	l1	d2	h2	l2	l3	l4	l5 min.	l5 max.	l6	Type	No.	EUR
38	99	158	19,5 - 23,5	4	47	91	5.2	4.5	6.4	26	13	5	30	11	2	HWS 252/ 2	<>
48	136	190	24,5 - 32	6	70	125	6.5	6	8	35	19	7	36	14	3	HWS 252/ 3	<>

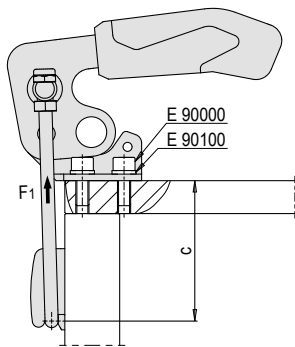

Type	F1	c min.	c max.
2	1.6 kN	24	49
3	3.2 kN	34,5	64