




**PRODUCT DESCRIPTION**

- » Shank ø 6 mm
- » For deburring or countersinking

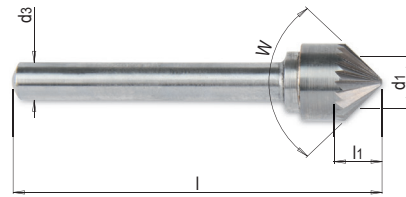

| Shape   | l  | l1 | d3 | W   | d1 | No.           | EUR |
|---|----|----|----|-----|----|---------------|-----|
|  | 50 | 6  | 6  | 60° | 6  | V 72276/60/ 6 | <>  |
|   | 53 | 8  | 6  | 60° | 8  | V 72276/60/ 8 | <>  |
|   | 55 | 10 | 6  | 60° | 10 | V 72276/60/10 | <>  |
|   | 57 | 12 | 6  | 60° | 12 | V 72276/60/12 | <>  |
|  | 50 | 4  | 6  | 90° | 4  | V 72276/90/ 4 | <>  |
|   | 50 | 6  | 6  | 90° | 6  | V 72276/90/ 6 | <>  |
|   | 53 | 8  | 6  | 90° | 8  | V 72276/90/ 8 | <>  |
|   | 55 | 10 | 6  | 90° | 10 | V 72276/90/10 | <>  |
|   | 57 | 12 | 6  | 90° | 12 | V 72276/90/12 | <>  |

 Cutting data on page IL