




Mitutoyo

PRODUCT DESCRIPTION

- » Titanium-coated measuring faces
- » 3-point centring for perfect measurement results
- » Thimble with scale and ratchet function

INCLUDED IN THE DELIVERY

- » Certificate of inspection and a plastic case

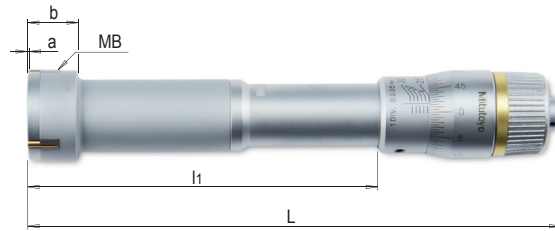

L	l1	a	b	SK ¹⁾	Tol.	Wt.	MB ²⁾	No.	EUR
104	59	2	2.5	0,001	+/-0,002	60 g	6- 8	MIA 10232/ 6- 8	< >
104	59	2	2.5	0,001	+/-0,002	60 g	8- 10	MIA 10232/ 8-10	< >
104	59	2	2.5	0,001	+/-0,002	60 g	10- 12	MIA 10232/10-12	< >
130	82	0.3	5.6	0,005	+/-0,002	150 g	12- 16	MIA 10232/12-16	< >
130	82	0.3	5.6	0,005	+/-0,002	160 g	16- 20	MIA 10232/16-20	< >
130	94	0.3	8.3	0,005	+/-0,003	260 g	20- 25	MIA 10232/20-25	< >
142	94	0.3	8.3	0,005	+/-0,003	280 g	25- 30	MIA 10232/25-30	< >
155	102	0.3	13	0,005	+/-0,003	290 g	30- 40	MIA 10232/30-40	< >
155	102	0.3	13	0,005	+/-0,003	330 g	40- 50	MIA 10232/40-50	< >
163	105	0.3	17	0,005	+/-0,003	440 g	50- 63	MIA 10232/50-63	< >

1) SK: scale in mm

2) MB: measuring range

i Pre-calibrated on request