





PRODUCT DESCRIPTION

- » Simple and tool-free assembly and removal thanks to patented spring mechanism
- » Loadable in any direction
- » 360° rotatable - positioning in load direction
- » 100% crack tested screw

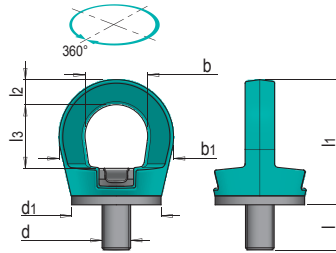

l	l1	l2	l3	b	b1	d1	d	WLL				No.	EUR
								max. kg	max. kg	max. kg	max. kg		
15	53	10	27	25	45	35	M 8	1,000	300	600	420	E 1272 M/ 8	<>
15	53	10	27	25	45	35	M10	1,500	500	1,000	700	E 1272 M/10	<>
20	63	12	32	30	55	43	M12	2,000	700	1,400	980	E 1272 M/12	<>
25	70	14	36	35	64	50	M16	4,000	1,500	3,000	2,100	E 1272 M/16	<>
30	81	16	41	40	73	54	M20	5,000	2,300	4,600	3,200	E 1272 M/20	<>
35	93	18	50	50	86	69	M24	6,500	3,200	6,400	4,500	E 1272 M/24	<>
45	114	25	60	60	110	90	M30	12,000	4,000	8,000	5,600	E 1272 M/30	<>
55	136	31	70	70	132	108	M36	15,000	7,000	14,000	9,800	E 1272 M/36	<>
65	153	36	72	80	152	126	M42	22,000	9,000	18,000	12,600	E 1272 M/42	<>
75	179	42	88	95	179	148	M48	30,000	12,000	24,000	16,900	E 1272 M/48	<>

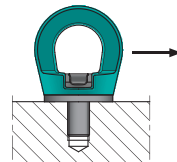

- Do not rotate under load!
- Rotate in the direction of force before loading!
- Hand tighten, do not use extension!