


PRODUCT DESCRIPTION

» For HER 1112, HER 1212 and HER 1412

MATERIAL

» 1.2083, hardened

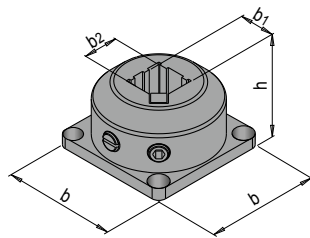

b	h	b1	b2	No.	EUR
51.5	29	15	15	HER 1118/15	<>
54	35	25	25	HER 1118/25	<>