
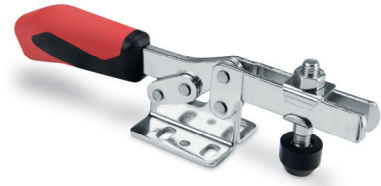


PRODUCT DESCRIPTION

- » Types 2 to 4 with hardened bushings
- » Ergonomic handle made of two components
- » Tempered and galvanised clamping screw with protective cap

MATERIAL

- » Steel, galvanised and passivated

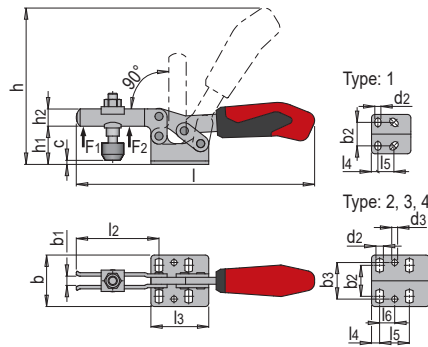

c min.	c max.	b	h	l	b1	h1	b2	d2	h2	l2	b3	d3	l3	l4	l5	l6	Type	No.	EUR
-5,5	0	25	57	79	4	14,5	16	4,6	7,5	28	-	-	25,5	6,3	11,5 - 15,5	-	0	HWS 200/ 0	<>
-3	2,5	34	79	120	5	19	18 - 21,5	5,2	10	42	-	-	34	5,5	13 - 14,5	-	1	HWS 200/ 1	<>
-1,5	5	42	113	162	6	24	19,5 - 29,5	5,6	13,2	64	28,5	5,6	38	6	26	12,7	2	HWS 200/ 2	<>
-2	9	45,5	135	206	8	32	22 - 31,8	6,5	15	73	31,6	5,1	50	7	25,7	13	3	HWS 200/ 3	<>
-4	24	58	201	287	10	45	29 - 43	8,5	20	113	43	8,5	57	8	41	20,5	4	HWS 200/ 4	<>

Type	F1	F2	l7	l8	d1	l1
0	0.25 kN	0.4 kN	9	5.5	M 4	25
1	0.8 kN	1.1 kN	18.7	8	M 5	30
2	1.0 kN	1.2 kN	32	16	M 6	35
3	1.8 kN	2.5 kN	38	14	M 8	45
4	2.0 kN	3.0 kN	63	27	M 8	65

