


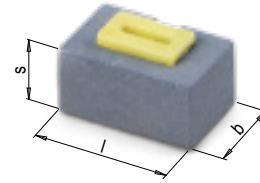























PRODUCT DESCRIPTION

- » For working with filing machines
- » Optimal for small surfaces
- » Good surfaces through even support
- » Different polishing stone qualities
- » With plastic insert for push rod



Version	Grit	l x b x s	Size	Pcs. / PU	No.	EUR
01 EDM stone	● 120	10 x 4,8 x 5,5	S	10	V 76215/01/S/120	<>
	● 180			10	V 76215/01/S/180	<>
	● 220			10	V 76215/01/S/220	<>
	● 320			10	V 76215/01/S/320	<>
	● 400			10	V 76215/01/S/400	<>
	● 600			10	V 76215/01/S/600	<>
	● 120	11 x 6,3 x 6,4	M	10	V 76215/01/M/120	<>
	● 180			10	V 76215/01/M/180	<>
	● 220			10	V 76215/01/M/220	<>
	● 320			10	V 76215/01/M/320	<>
	● 400			10	V 76215/01/M/400	<>
	● 600			10	V 76215/01/M/600	<>
	● 120	12,7 x 8 x 6,4	L	10	V 76215/01/L/120	<>
	● 180			10	V 76215/01/L/180	<>
	● 220			10	V 76215/01/L/220	<>
	● 320			10	V 76215/01/L/320	<>
	● 400			10	V 76215/01/L/400	<>
	● 600			10	V 76215/01/L/600	<>
02 Universal stone, oil soaked	● 120	10 x 4,8 x 5,5	S	10	V 76215/02/S/120	<>
	● 220			10	V 76215/02/S/220	<>
	● 320			10	V 76215/02/S/320	<>
	● 400			10	V 76215/02/S/400	<>
	● 600			10	V 76215/02/S/600	<>
	● 120			11 x 6,3 x 6,4	M	10
	● 220	10	V 76215/02/M/220			<>
	● 320	10	V 76215/02/M/320			<>
	● 400	10	V 76215/02/M/400			<>
	● 600	10	V 76215/02/M/600			<>
	● 120	12,7 x 8 x 6,4	L			10
	● 220			10	V 76215/02/L/220	<>
	● 320			10	V 76215/02/L/320	<>
	● 400			10	V 76215/02/L/400	<>
	● 600			10	V 76215/02/L/600	<>

Version	Grit	l x b x s	Size	Pcs. / PU	No.	EUR
03 Soft silicon carbide	 220	10 x 4,8 x 5,5	S	10	V 76215/03/S/220	<>
	 320			10	V 76215/03/S/320	<>
	 400			10	V 76215/03/S/400	<>
	 600			10	V 76215/03/S/600	<>
	 220	11 x 6,3 x 6,4	M	10	V 76215/03/M/220	<>
	 320			10	V 76215/03/M/320	<>
	 400			10	V 76215/03/M/400	<>
	 600			10	V 76215/03/M/600	<>
	 220	12,7 x 8 x 6,4	L	10	V 76215/03/L/220	<>
	 320			10	V 76215/03/L/320	<>
	 400			10	V 76215/03/L/400	<>
	 600			10	V 76215/03/L/600	<>
04 Semi-hard silicon carbide	 320	10 x 4,8 x 5,5	S	10	V 76215/04/S/320	<>
	 400			10	V 76215/04/S/400	<>
	 600			10	V 76215/04/S/600	<>
	 800			10	V 76215/04/S/800	<>
	 320	11 x 6,3 x 6,4	M	10	V 76215/04/M/320	<>
	 400			10	V 76215/04/M/400	<>
	 600			10	V 76215/04/M/600	<>
	 800			10	V 76215/04/M/800	<>
	 320	12,7 x 8 x 6,4	L	10	V 76215/04/L/320	<>
	 400			10	V 76215/04/L/400	<>
	 600			10	V 76215/04/L/600	<>
	 800			10	V 76215/04/L/800	<>

Type			Comparable to
01	EDM	For EDMed surfaces	V 76124
02	UNI	Universal stone, oil soaked	V 76130
03	SiCW	For medium-hard to hard steels (55 HRC)	V 76184
04	SiCM	For medium-hard to very hard steels (63 HRC)	V 76182