


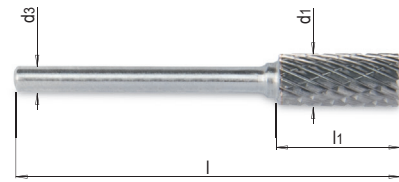


 




PREMIUM SOLID CARBIDE ROTARY BURR, CROSS CUT, SHANK Ø 3 V 72244

PRODUCT DESCRIPTION

- » Shank Ø3 mm
- » Long life
- » High cutting edge stability
- » For pre-toughened and hardened steel < 54 HRC and chrome steel



	Shape	d3	l	d1	l1	No.	EUR
A1	 Cylinder	3	43	6	13	V 72244/ A1/ 6,0x13,0	< >
A2	 Cylinder, cross lines	3	43	6	13	V 72244/ A2/ 6,0x13,0	< >
A3	 Cylinder, ball nose	3	43	6	14	V 72244/ A3/ 6,0x14,0	< >
E1	 Inverted cone	3	36	6	6	V 72244/ E1/ 6,0x 6,0	< >
G3	 Cone, pointed tip	3	43	6	13	V 72244/G3/ 6,0x13,0	< >
J1	 Ball	3	35	6	-	V 72244/ J1/ 6,0	< >
L2	 Tree, rounded tip	3	43	6	13	V 72244/ L2/ 6,0x13,0	< >
M4	 Drop	3	40	6	10	V 72244/M4/ 6,0x10,0	< >

 Cutting data on page PL