


### DESCRIZIONE DEL PRODOTTO

» Secondo DIN 6315C

### MATERIALE

» Acciaio bonificato, laccato

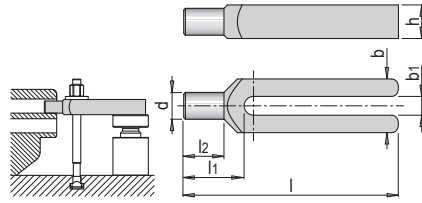

b	d	h	l1	l2	M <sup>1)</sup>	b1	l	N°	EUR
30	12	15	30	18	M8	9	100	HWS 119/ 9/100	<>
30	16	20	36	24	M10	11	125	HWS 119/11/125	<>
40	20	25	45	30	M12, M14	14	160	HWS 119/14/160	<>
40	20	25	45	30	M12, M14	14	200	HWS 119/14/200	<>
50	24	30	55	36	M16, M18	18	200	HWS 119/18/200	<>
50	24	30	55	36	M16, M18	18	250	HWS 119/18/250	<>
60	30	40	65	45	M20, M22	22	250	HWS 119/22/250	<>
60	30	40	65	45	M20, M22	22	315	HWS 119/22/315	<>

1) M: Adatto per vite di serraggio