





 


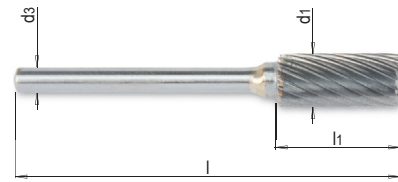

FRESA ROTATIVA IN VHM CON TAGLIENTI PER FINITURA, GAMBO Ø3 72246

DESCRIZIONE DEL PRODOTTO

- » Gambo Ø3 mm
- » Adatte per acciaio bonificato e temprato < 54 HRC e acciaio cromato



	Forma	d3	l	d1	l1	N°	EUR
A1	 Cilindro	3	43	6	13	V 72246/ A1/ 6,0x13,0	< >
A2	 Cilindro, fronte dentata	3	43	6	13	V 72246/ A2/ 6,0x13,0	< >
A3	 Cilindro tondo	3	43	6	14	V 72246/ A3/ 6,0x14,0	< >
E2	 Trapezio, fronte dentata	3	36	6	6	V 72246/ E2/ 6,0x 6,0	< >
G3	 Cono acuto	3	43	6	13	V 72246/ G3/ 6,0x13,0	< >
J1	 Sfera	3	35	6	-	V 72246/ J1/ 6,0	< >
L2	 Arco a pieno centro	3	43	6	13	V 72246/ L2/ 6,0x13,0	< >
M4	 Goccia	3	40	6	10	V 72246/M4/ 6,0x10,0	< >

 Valori di taglio a pagina PL