


MATERIALE

» Grafite Q70, Q60, Q40

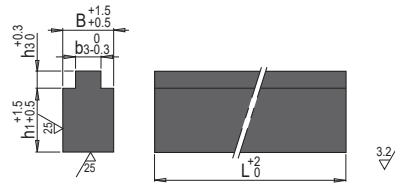

h3	b3	B	h1	L	Q70	EUR	Q60	EUR	Q40	EUR
13	10	15	30	500		-	V 92384/15/30/500	< >	V 92387/15/30/500	< >
13	10	15	50	500		-	V 92384/15/50/500	< >	V 92387/15/50/500	< >
13	20	22	30	500	V 92381/22/30/500	< >	V 92384/22/30/500	< >	V 92387/22/30/500	< >
13	20	22	50	500	V 92381/22/50/500	< >	V 92384/22/50/500	< >	V 92387/22/50/500	< >
13	20	30	30	500	V 92381/30/30/500	< >	V 92384/30/30/500	< >	V 92387/30/30/500	< >
13	20	30	50	500	V 92381/30/50/500	< >	V 92384/30/50/500	< >	V 92387/30/50/500	< >
13	20	40	30	500	V 92381/40/30/500	< >	V 92384/40/30/500	< >	V 92387/40/30/500	< >
13	20	40	50	500	V 92381/40/50/500	< >	V 92384/40/50/500	< >	V 92387/40/50/500	< >