


DESCRIZIONE DEL PRODOTTO

- » Grana diamantata con lega galvanica
- » Per macchine e supporto V 74485
- » Flessibile

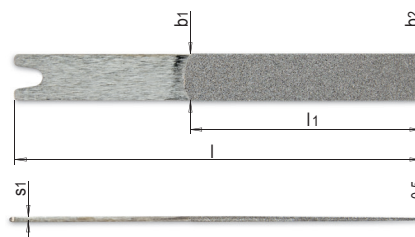

Forma	s1	l	l1	b1	b2	Grana	N°	EUR	
02		1	60	25	3	2	200	V 74480/02/25/ 3/ 2/200	<>
		1	60	25	3	2	400	V 74480/02/25/ 3/ 2/400	<>
		1	60	25	3	2	600	V 74480/02/25/ 3/ 2/600	<>
		1	60	25	4	2	150	V 74480/02/25/ 4/ 2/150	<>
		1	60	25	4	2	200	V 74480/02/25/ 4/ 2/200	<>
		1	60	25	4	2	400	V 74480/02/25/ 4/ 2/400	<>
		1	60	25	4	3	200	V 74480/02/25/ 4/ 3/200	<>
		1	60	25	4	3	400	V 74480/02/25/ 4/ 3/400	<>
		1	60	25	4	3	600	V 74480/02/25/ 4/ 3/600	<>
		1	70	40	3	2	200	V 74480/02/40/ 3/ 2/200	<>
		1	70	40	3	2	400	V 74480/02/40/ 3/ 2/400	<>
		1	70	40	3	2	600	V 74480/02/40/ 3/ 2/600	<>
		1	70	40	4	3	200	V 74480/02/40/ 4/ 3/200	<>
		1	70	40	4	3	400	V 74480/02/40/ 4/ 3/400	<>
		1	70	40	4	3	600	V 74480/02/40/ 4/ 3/600	<>
04		1	60	25	4	4	150	V 74480/04/25/ 4/ 4/150	<>
		1	60	25	4	4	200	V 74480/04/25/ 4/ 4/200	<>
		1	60	25	4	4	400	V 74480/04/25/ 4/ 4/400	<>
		1	70	40	6	6	150	V 74480/04/40/ 6/ 6/150	<>
		1	70	40	6	6	200	V 74480/04/40/ 6/ 6/200	<>
		1	70	40	6	6	400	V 74480/04/40/ 6/ 6/400	<>
		1	70	40	8	8	150	V 74480/04/40/ 8/ 8/150	<>
		1	70	40	8	8	200	V 74480/04/40/ 8/ 8/200	<>
		1	70	40	8	8	400	V 74480/04/40/ 8/ 8/400	<>
		1	90	60	8	8	150	V 74480/04/60/ 8/ 8/150	<>
		1	90	60	8	8	200	V 74480/04/60/ 8/ 8/200	<>
		1	90	60	8	8	400	V 74480/04/60/ 8/ 8/400	<>
		1	70	40	10	10	150	V 74480/04/40/10/10/150	<>
		1	70	40	10	10	200	V 74480/04/40/10/10/200	<>
		1	70	40	10	10	400	V 74480/04/40/10/10/400	<>
		1	90	60	10	10	150	V 74480/04/60/10/10/150	<>
		1	90	60	10	10	200	V 74480/04/60/10/10/200	<>
		1	90	60	10	10	400	V 74480/04/60/10/10/400	<>