



DESCRIZIONE DEL PRODOTTO

- » Gambo Ø3 mm
- » Perfetta aderenza ai bordi, grazie alle lamelle flessibili
- » Ideale per la sbozzatura
- » Lamelle abrasive in corindone normale
- » Sino a 55 HRC

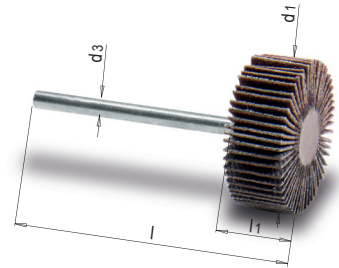

d3	l	d1	l1	Grana	 Pz. / UDC	N°	EUR
3	50	10	10	80	10	V 74962/10/10/ 80	<>
3	50	10	10	120	10	V 74962/10/10/120	<>
3	50	10	10	150	10	V 74962/10/10/150	<>
3	50	10	10	240	10	V 74962/10/10/240	<>
3	55	15	15	80	10	V 74962/15/15/ 80	<>
3	55	15	15	120	10	V 74962/15/15/120	<>
3	55	15	15	150	10	V 74962/15/15/150	<>
3	50	20	10	80	10	V 74962/20/10/ 80	<>
3	50	20	10	120	10	V 74962/20/10/120	<>
3	50	20	10	150	10	V 74962/20/10/150	<>
3	50	20	10	320	10	V 74962/20/10/320	<>
3	50	25	10	80	10	V 74962/25/10/ 80	<>
3	50	25	10	120	10	V 74962/25/10/120	<>
3	50	25	10	150	10	V 74962/25/10/150	<>
3	45	30	5	80	10	V 74962/30/ 5/ 80	<>
3	45	30	5	120	10	V 74962/30/ 5/120	<>
3	45	30	5	150	10	V 74962/30/ 5/150	<>
3	45	30	5	240	10	V 74962/30/ 5/240	<>
3	45	30	5	320	10	V 74962/30/ 5/320	<>
3	50	30	10	80	10	V 74962/30/10/ 80	<>
3	50	30	10	120	10	V 74962/30/10/120	<>
3	50	30	10	150	10	V 74962/30/10/150	<>
3	50	30	10	240	10	V 74962/30/10/240	<>
3	50	30	10	320	10	V 74962/30/10/320	<>