


### PRODUKTBESCHREIBUNG

- » Zum Heben von Flach- und Rundmaterial geeignet
- » Sicherheitskoeffizient größer 3
- » Neodym-Magnete für hohe Hebekräfte

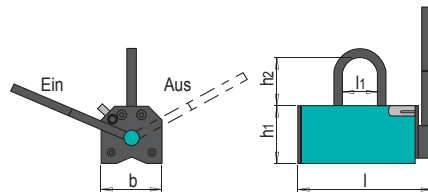

l	b	h1	h2	l1	s min.	d max.	kg max. RM <sup>1)</sup>	kg max. FM <sup>2)</sup>	Nr.	EUR
125	68	70	54	40	15	200	50	<b>100</b>	THL 100/ 100	<>
190	98	87	70	50	25	180	125	<b>250</b>	THL 100/ 250	<>
255	98	87	70	50	30	180	215	<b>500</b>	THL 100/ 500	<>
320	140	110	105	65	50	600	450	<b>1.000</b>	THL 100/1000	<>

1) kg max. RM: max. Tragkraft Rundmaterial

2) kg max. FM: max. Tragkraft Flachmaterial

