


### PRODUKTBESCHREIBUNG

- » Nach DIN 6319G
- » Durch den großen Durchmesser besonders geeignet zum Spannen über den Schlitz bei Spanneisen

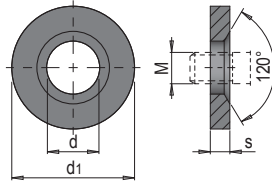

d	d1	s	M	Nr.	EUR
9,6	24	5	M8	HWS 9019/ 8	<>
12	30	5	M10	HWS 9019/10	<>
14,2	36	6	M12	HWS 9019/12	<>
19	44	7	M16	HWS 9019/16	<>
23,2	50	8	M20	HWS 9019/20	<>

