


### PRODUKTBESCHREIBUNG

- » Passend für GESU 2300/N
- » Optimal für schwere Arbeiten
- » Stabiler Grundkörper
- » Hochwertige galvanische Beschichtung

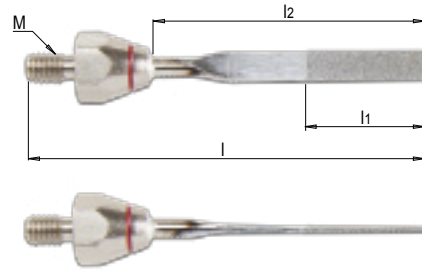

	Form	b	M	l	l1	a	d	l2	Korn	Nr.	EUR
01		0,7	M 4	50	15	4	-	35	● 200/D91	V 74470/01/4 x 35/200	<>
		0,7	M 4	50	15	4	-	35	● 320/D54	V 74470/01/4 x 35/320	<>
		0,7	M 4	50	15	4	-	35	○ 600/D30	V 74470/01/4 x 35/600	<>
		1	M 4	140	40	5	-	125	● 200/D91	V 74470/01/5 x 125/200	<>
		1	M 4	140	40	5	-	125	● 320/D54	V 74470/01/5 x 125/320	<>
		1	M 4	140	40	5	-	125	○ 600/D30	V 74470/01/5 x 125/600	<>
03		-	M 4	40	15	-	3	25	● 200/D91	V 74470/03/3 x 25/200	<>
		-	M 4	40	15	-	3	25	● 320/D54	V 74470/03/3 x 25/320	<>
		-	M 4	40	15	-	3	25	○ 600/D30	V 74470/03/3 x 25/600	<>
05		-	M 4	40	15	3	-	25	● 200/D91	V 74470/05/3 x 25/200	<>
		-	M 4	40	15	3	-	25	● 320/D54	V 74470/05/3 x 25/320	<>
		-	M 4	40	15	3	-	25	○ 600/D30	V 74470/05/3 x 25/600	<>