
 



 






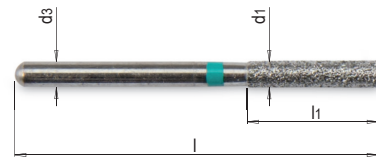











PRODUKTBESCHREIBUNG

- » Für feinste Konturen
- » Mit Reduzierhülse GESM 4920 verwenden
- » Verschiedene Körnungen im Set



Form		Korn	d3	l	w	d1	l1	 Stk. / VPE	Nr.	EUR
A1			1,6	20	-	1	4	3	V 72610/A1/ 1,0x 4	<>
			1,6	20	-	1,4	8	5	V 72610/A1/ 1,4x 8	<>
A3			1,6	20	-	1	4	2	V 72610/A3/ 1,0x 4	<>
G3			1,6	20	5°	1	8	4	V 72610/G3/ 1,0x 8	<>
			1,6	20	6°	1,2	8	4	V 72610/G3/ 1,2x 8	<>
			1,6	20	7°	1,4	8	5	V 72610/G3/ 1,4x 8	<>
			1,6	20	9°	1,6	8	4	V 72610/G3/ 1,6x 8	<>
J1			1,6	20	-	1	-	5	V 72610/J1/ 1,0	<>
			1,6	20	-	1,2	-	4	V 72610/J1/ 1,2	<>
			1,6	20	-	1,6	-	5	V 72610/J1/ 1,6	<>
			1,6	20	-	2,1	-	5	V 72610/J1/ 2,1	<>

Farbe		Korn
	schwarz	80 / D213
	grün	100 / D151
	blau	120 / D126
	rot	240 / D54
	gelb	400 / D30