


PRODUKTBESCHREIBUNG

- » Schaft Ø6 mm
- » Zum Feinschleifen und Reinigen
- » Kombination aus Schleifvlies und Schleifleinen
- » Normalkorund
- » Bis 55 HRC

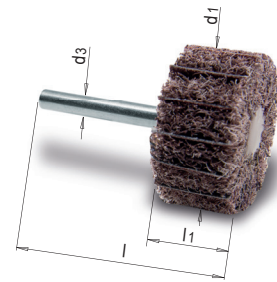

d3	l	d1	l1	Korn	 Stk. / VPE	Nr.	EUR
6	70	30	30	80	10	V 74974/30x30/ 80	< >
6	60	40	20	80	10	V 74974/40x20/ 80	< >
6	60	40	20	150	10	V 74974/40x20/150	< >
6	60	40	20	240	10	V 74974/40x20/240	< >
6	70	40	30	80	10	V 74974/40x30/ 80	< >
6	70	40	30	150	10	V 74974/40x30/150	< >