




**PRODUCT DESCRIPTION**

- » Low overall height
- » HER 1912 clamping spigot WEDM for clamping operations required
- » Max. tightening torque 6 Nm

**MATERIAL**

- » 1.2083

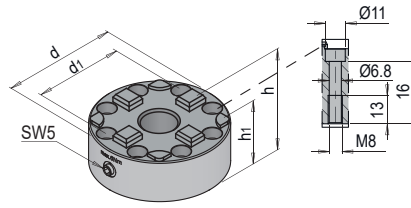

d	d1	h	h1	No.	EUR
75	60	30	27	HER 3534/75	<>