
 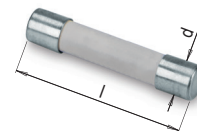


PRODUCT DESCRIPTION

» Suitable for profiTEMP+, profiTEMP TM and profiTEMP IM



d	l	Type	 Pcs. / PU	No.	EUR
6	32	500VAC/16A/FF	10	RHZ 1030/500/16/6x32/FF	< >