


PRODUCT DESCRIPTION

- » Particularly suitable for mounting gate assemblies
- » Wrench sizes with tight tolerances
- » Thin-walled, for working even in the tightest spaces
- » Bi-hexagon with anti-slip drive profile



DIN 3124

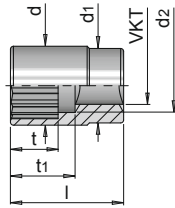

MATERIAL

- » Chrome vanadium steel, nickel-chrome plated and thus chip-proof

d	d1	d2	l	t	t1	VKT ¹⁾	SW	No.	EUR
14.3	14.3	9	23	8	14.9	6,3 mm / 1/4"	10	V 34412/1/4/10	<>
16.5	16.5	11	23	9.5	14.3	6,3 mm / 1/4"	12	V 34412/1/4/12	<>
26.2	25	18	38	16	21	12,5 mm / 1/2"	19	V 34412/1/2/19	<>
32	26	21	42	18.5	24.9	12,5 mm / 1/2"	24	V 34412/1/2/24	<>

1) VKT: Square drive