

**PRODUCT DESCRIPTION**

- » Shank Ø3 mm
- » Long life
- » High cutting edge stability
- » For pre-toughened and hardened steel < 54 HRC and chrome steel




Set contents	No.	EUR
» All V 72224 Mini rotary burrs in a set	V 72224/Set-20	< >

PREMIUM SOLID CARBIDE MINI ROTARY BURR, CROSS CUT

V 72224

**PRODUCT DESCRIPTION**

- » Shank Ø3 mm
- » Long life
- » High cutting edge stability
- » For pre-toughened and hardened steel < 54 HRC and chrome steel

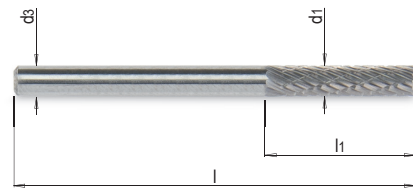

	Shape	d3	l	d1	l1	No.	EUR
A1	Cylinder	3	38	3	14	V 72224/ A1/ 3,0x14,0	< >
A2	Cylinder, cross lines	3	38	3	14	V 72224/ A2/ 3,0x14,0	< >
A3	Cylinder, ball nose	3	38	3	14	V 72224/ A3/ 3,0x14,0	< >
E1	Inverted cone	3	38	3	3	V 72224/ E1/ 3,0x 3,0	< >
G3	Cone, pointed tip	3	38	3	12	V 72224/ G3/ 3,0x12,0	< >
J1	Ball	3	38	2.5	-	V 72224/ J1/ 2,5	< >
		3	38	3	-	V 72224/ J1/ 3,0	< >
L1	Tree, pointed tip	3	38	3	12	V 72224/ L1/ 3,0x12,0	< >
L2	Tree, rounded tip	3	38	3	12	V 72224/ L2/ 3,0x12,0	< >
M4	Drop	3	38	3	6	V 72224/M4/ 3,0x 6,0	< >

Cutting data on page PL