


PRODUCT DESCRIPTION

- » High speed motor, perfect for processing the hardest materials
- » Efficient tool change due to keyless quick clamping system with high clamping force
- » Smooth operation even at maximum speed
- » Ergonomic aluminium housing with built-in front fan against dirt and dust
- » Integrated motor cooling for longest switch-on and service life
- » Illuminated on/off switch conveniently located on the handpiece

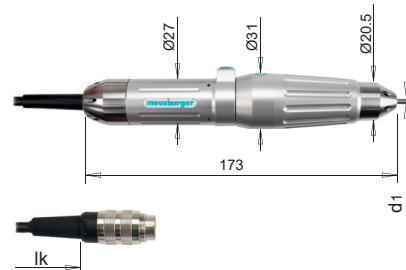

INCLUDED IN THE DELIVERY

- » Ø3 mm collet for quick-action clamping chuck (GESM 20015) with slotted spring pin
- » Collet wrench (20016) and locking wrench (GESM 20017)
- » Motor cable

Wt.	d1	lk ¹⁾	Output	n	No.	EUR
336 g	3	1.85 m	260 W	1,000 - 80,000 min ⁻¹	GESM 2016/260/80	< >

1) lk: cable length

i Spare parts and repair by request

CHARACTERISTICS

GESM 2016	Value
Motor type	Brushless DC motor
Torque	8.9 Ncm
Concentricity	< 0,02 mm