
 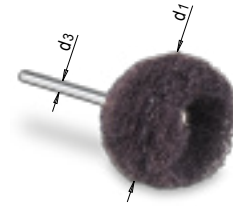


PRODUCT DESCRIPTION

- » For cleaning or fine polishing
- » Suitable for steel or non-ferrous metals
- » Fits the contour optimally



	Version		d3	d1	 Pcs. / PU	No.	EUR
01	extra rough	●	3	25	10	V 74982/01/25	< >
02	very rough	●	3	25	10	V 74982/02/25	< >
03	rough	●	3	25	10	V 74982/03/25	< >
			3	40	10	V 74982/03/40	< >
04	medium	●	3	30	10	V 74982/04/30	< >
			3	40	10	V 74982/04/40	< >
05	medium SiC	●	3	25	10	V 74982/05/25	< >
			3	40	10	V 74982/05/40	< >
06	fine	●	3	25	10	V 74982/06/25	< >
			3	40	10	V 74982/06/40	< >
07	very fine	●	3	25	10	V 74982/07/25	< >
			3	40	10	V 74982/07/40	< >
08	ultra fine	●	3	25	10	V 74982/08/25	< >