




## PRODUCT DESCRIPTION

- » Hardened and stainless slide and rail
- » With rounded measuring tips, ideal for internal measurement
- » IP 65: protected against ingress of water and dust
- » Rapid switching from mm to inches and vice versa, in any position

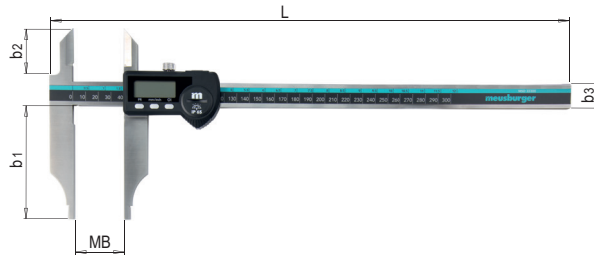

## INCLUDED IN THE DELIVERY

- » Certificate of calibration, a battery (CR2032) and a wooden case

L	b1	b2	b3	Tol.	Wt.	MB <sup>1)</sup>	No.	#CU#
410	90	40	20	+/-0,03	471 g	<b>0-300</b>	MSD 22300/300	XX,YY
650	125	55	25	+/-0,04	1137 g	<b>0-500</b>	MSD 22300/500	XX,YY
905	150	55	25	+/-0,05	2083 g	<b>0-800</b>	MSD 22300/800	XX,YY

1) MB: measuring range

Pre-calibrated