

PRODUCT DESCRIPTION

- » Diamond grit with galvanic bond
- » Plastic coated shank




Set contents	Grit	No.	EUR
» V 74415 Diamond hand file, type 02 and 04 in a set	● 150	V 74415/Set-06/150	< >
	● 200	V 74415/Set-06/200	< >
	● 400	V 74415/Set-06/400	< >
» 74415 Diamond hand file, type 04, all grit sizes in set	● 150	V 74415/Set-12	< >
	● 200		
	● 400		

DIAMOND HAND FILE, TAPERED NEEDLE 50

V 74415

PRODUCT DESCRIPTION

- » Diamond grit with galvanic bond
- » Plastic coated shank

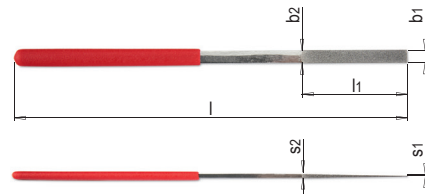

Shape	Grit	b2	s1	s2	l	l1	b1	No.	EUR
02	● 150	3	0.4	1.5	180	50	2	V 74415/02/2 /150	< >
	● 200	3	0.4	1.5	180	50	2	V 74415/02/2 /200	< >
	● 400	3	0.4	1.5	180	50	2	V 74415/02/2 /400	< >
	● 150	4	0.5	2	180	50	3	V 74415/02/3 /150	< >
	● 200	4	0.5	2	180	50	3	V 74415/02/3 /200	< >
	● 400	4	0.5	2	180	50	3	V 74415/02/3 /400	< >
04	● 150	2.5	0.5	2	180	50	2.5	V 74415/04/2,5/150	< >
	● 200	2.5	0.5	2	180	50	2.5	V 74415/04/2,5/200	< >
	● 400	2.5	0.5	2	180	50	2.5	V 74415/04/2,5/400	< >
	● 150	4	0.5	2	180	50	4	V 74415/04/4 /150	< >
	● 200	4	0.5	2	180	50	4	V 74415/04/4 /200	< >
	● 400	4	0.5	2	180	50	4	V 74415/04/4 /400	< >
	● 150	6	0.5	2	180	50	6	V 74415/04/6 /150	< >
	● 200	6	0.5	2	180	50	6	V 74415/04/6 /200	< >
	● 400	6	0.5	2	180	50	6	V 74415/04/6 /400	< >
	● 150	8	0.5	2.5	180	50	8	V 74415/04/8 /150	< >
	● 200	8	0.5	2.5	180	50	8	V 74415/04/8 /200	< >
	● 400	8	0.5	2.5	180	50	8	V 74415/04/8 /400	< >